

Part No: BS23C6-060C

Filters & Strainers

Basket Strainers

Desc: 6 CPVC BASKET STRAINER FLG EPDM C6 MESH

MSRP: 12869.7

Part Code: 297

Weight(lbs): 68.123


Weight(kg): 30.9

Weight(gm): 30900

Size: 6"

Color: GRAY

Material: CPVC

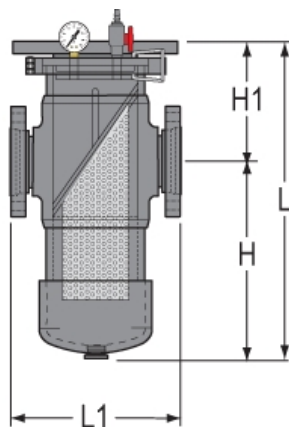

Connection Flanged

O-Ring EPDM

Mesh Sieve # 6 = (1/8")

H = 18- 7/8

Cv = 630
Values

No of Bolts = 8

Bolt = 9- 1/2
Circle Dia.

Bolt Size = 3/4

H1 = 11- 9/16

L = 30- 7/16

L1 = 17- 1/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

