

Part No: BS23C6-120C

Filters & Strainers

Basket Strainers

Desc: 12 CPVC BASKET STRAINR FLNG EPDM C6 MESH

MSRP: 30928.09

Part Code: 297

Weight(lbs): 200.422


Weight(kg): 90.91

Weight(gm): 90910

Size: 12"

Color: GRAY

Material: CPVC

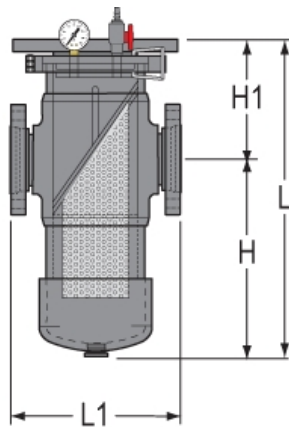

Connection Flanged

O-Ring EPDM

Mesh Sieve # 6 = (1/8")

H = 34-5/16

H1 = 17-1/8

L = 52-1/2

L1 = 28- 1/8

Cv = 1063
Values

No of Bolts = 12

Bolt Circle Dia. = 17

Bolt Size = 7/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

