

Part No: BS23P6-015

Filters & Strainers

Basket Strainers

Desc: 1-1/2 PVC BASKET STRANR FLG EPDM P6 MESH

MSRP: 1488.6

Part Code: 295

Weight(lbs): 11.729

Weight(kg): 5.32

Weight(gm): 5320

Size: 1-1/2"


Color: GRAY

Material: PVC

Connection Flanged

O-Ring EPDM

Mesh Sieve # 6 = (1/8")

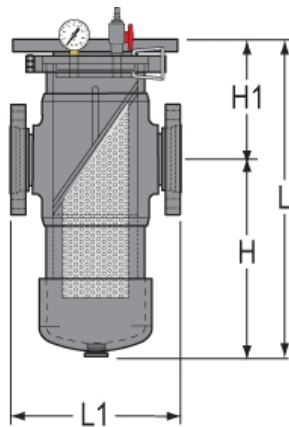

H = 10-3/4

H1 = 8

L = 18-3/4

L1 = 8-3/4

Cv = 46
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

