

Part No: BS23P6-080

Filters & Strainers

Basket Strainers

Desc: 8 PVC BASKET STRAINER FLG EPDM P6 MESH

MSRP: 12715.56

Part Code: 295

Weight(lbs): 107.354


Weight(kg): 48.695

Weight(gm): 48695

Size: 8"

Color: GRAY

Material: PVC

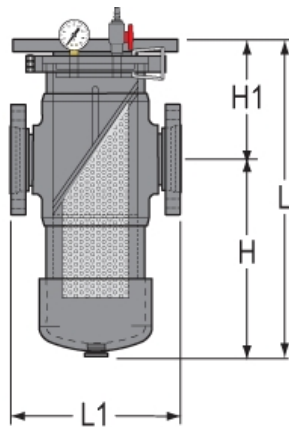

Connection Flanged

O-Ring EPDM

Mesh Sieve # 6 = (1/8")

H = 24- 1/2

H1 = 12-9/16

L = 37- 1/16

L1 = 20- 1/2

Cv = 750
Values

No of Bolts = 8

Bolt Circle Dia. = 11- 3/4

Bolt Size = 3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

