

Part No: BS23P6-100

Filters & Strainers

Basket Strainers

Desc: 10 PVC BASKET STRAINER FLG EPDM P6 MESH

MSRP: 16952.52

Part Code: 295

Weight(lbs): 152.042


Weight(kg): 68.965

Weight(gm): 68965

Size: 10"

Color: GRAY

Material: PVC

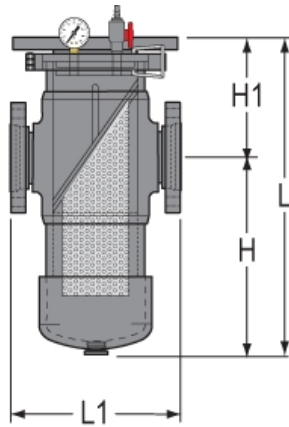

Connection Flanged

O-Ring EPDM

Mesh Sieve # 6 = (1/8")

H = 27- 1/8	H1 = 16- 5/8	L = 43-3/4	Bolt Size = 7/8	L1 = 26
Cv = 893	No of Bolts = 12	Bolt Circle Dia. = 14- 1/4		

Injection Molded Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch
- L** = Overall length of fittings; $\pm 1/16$ inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/16$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.
- W** = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

