

Part No: BS27S6-015C

Filters & Strainers

Basket Strainers

Desc: 1-1/2 CPVC BASKET STRNR SPG EPDM SS6 MSH

MSRP: 2557.12

Part Code: 297

Weight(lbs): 12.302


Weight(kg): 5.58

Weight(gm): 5580

Size: 1-1/2"

Color: GRAY

Material: CPVC

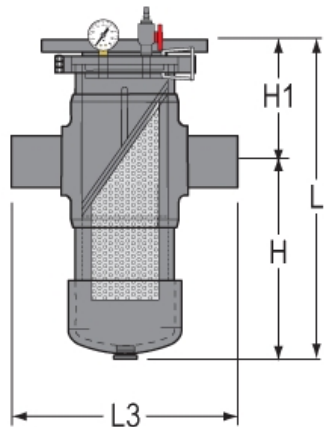

Connection Spigot

O-Ring EPDM

Mesh Sieve # 6 = (1/8")

H = 10- 1/4

H1 = 7- 7/8

L = 18- 1/8

L3 = 11

Cv = 46
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

