

Part No: BS27S6-040C

Filters & Strainers

Basket Strainers

Desc: 4 CPVC BASKET STRAINER SPG EPDM SS6 MESH

MSRP: 6750.12

Part Code: 297

Weight(lbs): 28.25

Weight(kg): 12.814

Weight(gm): 12814

Size: 4"


Color: GRAY

Material: CPVC

Connection Spigot

O-Ring EPDM

Mesh Sieve # 6 = (1/8")

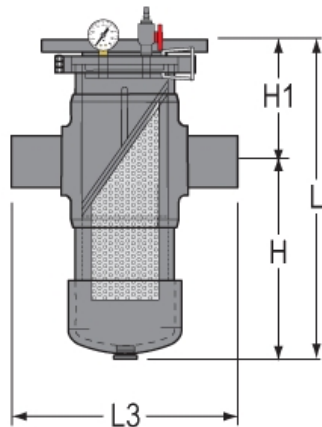

H = 17- 1/2

H1 = 9

L = 26- 1/2

L3 = 17- 1/2

Cv = 270
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

