

Part No: BS27S6-100C

Filters & Strainers

Basket Strainers

Desc: 10 CPVC BASKET STRAINER SPG EPDM S6 MESH

MSRP: 22445.29

Part Code: 297

Weight(lbs): 200.422

Weight(kg): 90.91

Weight(gm): 90910

Size: 10"


Color: GRAY

Material: CPVC

Connection Spigot

O-Ring EPDM

Mesh Sieve # 6 = (1/8")

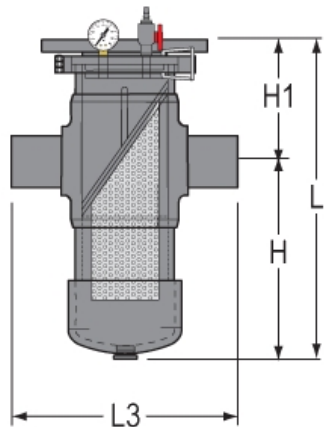

H = 27- 1/8

H1 = 16- 5/8

L = 43- 1/4

L3 = 34- 1/2

Cv = 893
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

