

Part No: BS32C6-005C

Filters & Strainers

Basket Strainers

Desc: 1/2 CPVC BASKET STRAINER SOC FKM C6 MESH

MSRP: 1119.46

Part Code: 297

Weight(lbs): 3.325


Weight(kg): 1.508

Weight(gm): 1508

Size: 1/2"

Color: GRAY

Material: CPVC

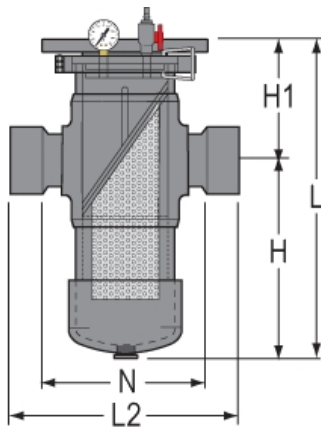

H = 5-11/16

H1 = 4-1/2

L = 10-3/16

L2 = 6-1/2

N = 4-3/4

Cv = 4.5

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

