

Part No: BS32C6-007C

Filters & Strainers

Basket Strainers

Desc: 3/4 CPVC BASKET STRAINER SOC FKM C6 MESH

MSRP: 1119.46

Part Code: 297

Weight(lbs): 3.285

Weight(kg): 1.49

Weight(gm): 1490

Size: 3/4"


Color: GRAY

Material: CPVC

Connection Socket

O-Ring FKM

Mesh Sieve # 6 = (1/8")

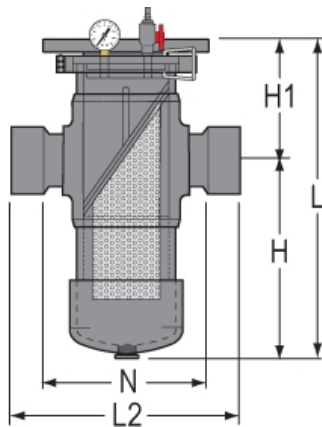

H = 5-11/16

H1 = 4-1/2

L = 10-3/16

L2 = 6-7/16

N = 4-3/8

Cv = 10

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

