

Part No: BS32C6-030C

Filters & Strainers

Basket Strainers

Desc: 3 CPVC BASKET STRAINER SOC FKM C6 MESH

MSRP: 4799.37

Part Code: 297

Weight(lbs): 24.582


Weight(kg): 11.15

Weight(gm): 11150

Size: 3"

Color: GRAY

Material: CPVC

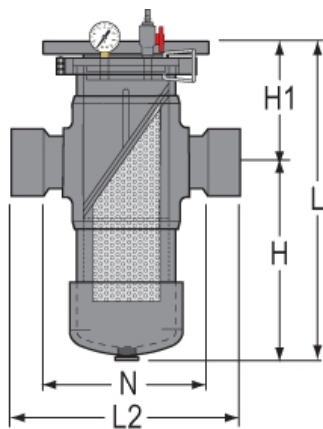

Connection Socket

O-Ring FKM

Mesh Sieve # 6 = (1/8")

H = 14-1/4

H1 = 9-1/8

L = 22-7/8

L2 = 16-1/8

N = 11-5/8

Cv = 172

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

