

Part No: BS32C6-080C

Filters & Strainers

Basket Strainers

Desc: 8 CPVC BASKET STRAINER SOC FKM C6 MESH

MSRP: 12031.64

Part Code: 297

Weight(lbs): 109.261


Weight(kg): 49.56

Weight(gm): 49560

Size: 8"

Color: GRAY

Material: CPVC

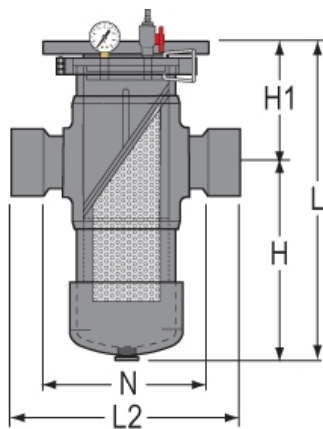

Connection Socket

O-Ring FKM

Mesh Sieve # 6 = (1/8")

H = 24- 1/2

H1 = 12- 9/16

L = 37- 1/16

L2 = 30- 1/2

N = 22

Cv = 750

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

