

Part No: BS33C6-030C

Filters & Strainers

Basket Strainers

Desc: 3 CPVC BASKET STRAINER FLG FKM C6 MESH

MSRP: 5750.46

Part Code: 297

Weight(lbs): 26.782


Weight(kg): 12.148

Weight(gm): 12148

Size: 3"

Color: GRAY

Material: CPVC

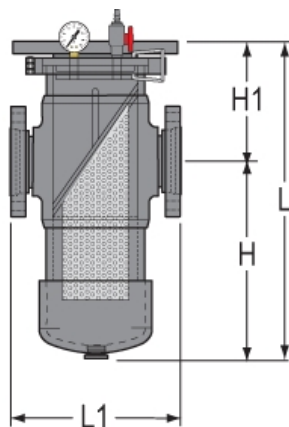

Connection Flanged

O-Ring FKM

Mesh Sieve # 6 = (1/8")

No of Bolts = 4

Bolt Circle Dia. = 6

Bolt Size = 5/8

L1 = 11- 5/8

Cv = 172
Values

H = 14-1/4

H1 = 9-1/8

L = 22-7/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

