

Part No: BS33C6-060C

Filters & Strainers

Basket Strainers

Desc: 6 CPVC BASKET STRAINER FLG FKM C6 MESH

MSRP: 14461.07

Part Code: 297

Weight(lbs): 77.916


Weight(kg): 35.342

Weight(gm): 35342

Size: 6"

Color: GRAY

Material: CPVC

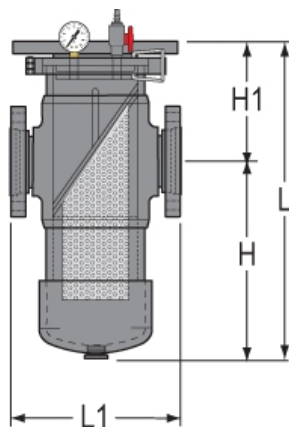

Connection Flanged

O-Ring FKM

Mesh Sieve # 6 = (1/8")

H = 18- 7/8

H1 = 11- 9/16

L = 30- 7/16

L1 = 17- 1/8

Cv = 630
Values

No of Bolts = 8

Bolt Circle Dia. = 9- 1/2

Bolt Size = 3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

