

Part No: BS33C6-100C

Filters & Strainers

Basket Strainers

Desc: 10 CPVC BASKET STRANER FLG FKM C6 MESH

MSRP: 25400.51

Part Code: 297

Weight(lbs): 144.619


Weight(kg): 65.598

Weight(gm): 65598

Size: 10"

Color: GRAY

Material: CPVC

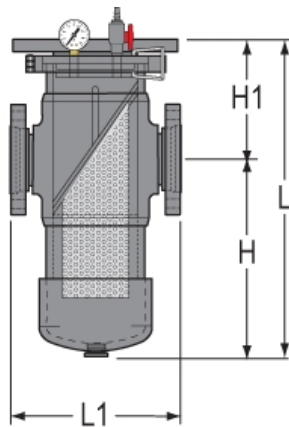

Connection Flanged

O-Ring FKM

Mesh Sieve # 6 = (1/8")

H = 27- 1/8

H1 = 16- 5/8

L = 43-3/4

No of Bolts = 12

Bolt Circle Dia. = 14- 1/4

Bolt Size = 7/8

L1 = 26

Cv = 893
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

