

Part No: BS33P6-040

Filters & Strainers

Basket Strainers

Desc: 4 PVC BASKET STRAINER FLGD FKM P6 MESH

MSRP: 5080.09

Part Code: 295

Weight(lbs): 30.027


Weight(kg): 13.62

Weight(gm): 13620

Size: 4"

Color: GRAY

Material: PVC

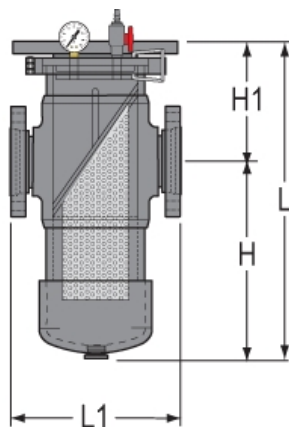

Connection Flanged

O-Ring FKM

Mesh Sieve # 6 = (1/8")

H = 17-3/4	H1 = 9-1/8	L = 26-3/8	Bolt Size = 5/8	L1 = 12
Cv = 270	No of Bolts = 8	Bolt Circle Dia.		

Injection Molded Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch
- L** = Overall length of fittings; ± 1/16 inch.
- M** = Outside diameter of socket/thread hub; ± 1/16 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.
- W** = Height of cap; ± 1/16 inch

Typical Molded Dimension References

