

Part No: BS33P6-120

Filters & Strainers

Basket Strainers

Desc: 12 PVC BASKET STRAINER FLG FKM P6 MESH

MSRP: 26064.02

Part Code: 295

Weight(lbs): 197.446


Weight(kg): 89.56

Weight(gm): 89560

Size: 12"

Color: GRAY

Material: PVC

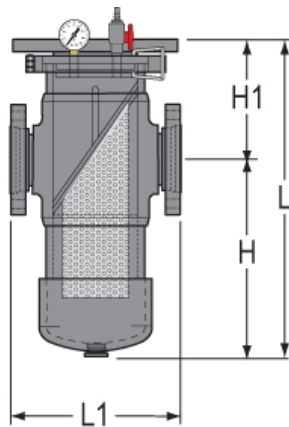

Connection Flanged

O-Ring FKM

Mesh Sieve # 6 = (1/8")

H = 34-5/16

H1 = 17-1/8

L = 52-1/2

L1 = 28- 1/8

Cv = 1063
Values

No of Bolts = 12

Bolt Circle Dia. = 17

Bolt Size = 7/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

