

Part No: BS33S6-025

Filters & Strainers

Basket Strainers

Desc: 2-1/2 PVC BASKT STRNR FLG FKM SS6 MESH

MSRP: 4131.8

Part Code: 295

Weight(lbs): 14.11


Weight(kg): 6.4

Weight(gm): 6400

Size: 2-1/2"

Color: GRAY

Material: PVC

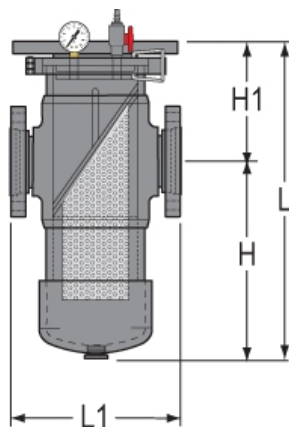

Connection Flanged

O-Ring FKM

Mesh Sieve # 6 = (1/8")

H = 10- 1/4

H1 = 7- 7/8

L = 18- 1/8

L1 = 8- 3/4

Cv = 110
Values

No of Bolts = 4

Bolt Circle Dia. = 5- 1/2

Bolt Size = 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

