

Part No: BS37C6-020C

Filters & Strainers

Basket Strainers

Desc: 2 CPVC BASKET STRAINER SPG FKM C6 MESH

MSRP: 2260.32

Part Code: 297

Weight(lbs): 12.015

Weight(kg): 5.45

Weight(gm): 5450

Size: 2"


Color: GRAY

Material: CPVC

Connection Spigot

O-Ring FKM

Mesh Sieve # 6 = (1/8")

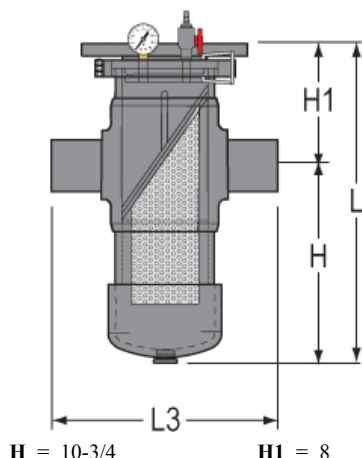

H = 10-3/4

H1 = 8

L = 18-3/4

L3 = 11

Cv = 72
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

