

**Part No:** BS37P6-025

**Filters & Strainers**

**Basket Strainers**

**Desc:** 2-1/2 PVC BASKET STRNR SPG FKM P6 MESH

**MSRP:** 2662.21

**Part Code:** 295

**Weight(lbs):** 19.061

**Weight(kg):** 8.646

**Weight(gm):** 8646

**Size:** 2-1/2"


**Color:** GRAY

**Material:** PVC

**Connection** Spigot

**O-Ring** FKM

**Mesh Sieve** # 6 = (1/8")

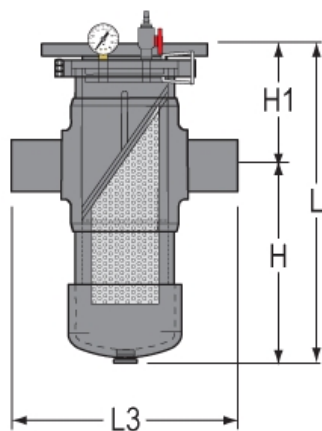

**H** = 10-3/4

**H1** = 8

**L** = 18-3/4

**L3** = 12-7/8

**Cv** = 110  
**Values**

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

