

**Part No:** BS37S6-010C

**Filters & Strainers**

**Basket Strainers**

**Desc:** 1 CPVC BASKET STRAINER SPG FKM S6 MESH

**MSRP:** 1529.1

**Part Code:** 297

**Weight(lbs):** 4.034


**Weight(kg):** 1.83

**Weight(gm):** 1830

**Size:** 1'

**Color:** GRAY

**Material:** CPVC

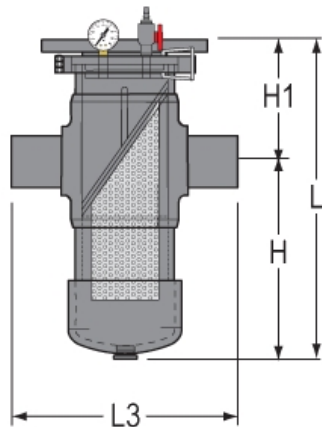

**Connection** Spigot

**O-Ring** FKM

**Mesh Sieve** # 6 = (1/8")

**H** = 5-11/16

**H1** = 4-1/2

**L** = 10-3/16

**L3** = 10

**Cv** = 15  
**Values**

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

