

Part No: BS37S6-030C

Filters & Strainers

Basket Strainers

Desc: 3 CPVC BASKET STRAINER SPG FKM S6 MESH

MSRP: 5861.01

Part Code: 297

Weight(lbs): 26.356

Weight(kg): 11.955

Weight(gm): 11955

Size: 3"


Color: GRAY

Material: CPVC

Connection Spigot

O-Ring FKM

Mesh Sieve # 6 = (1/8")

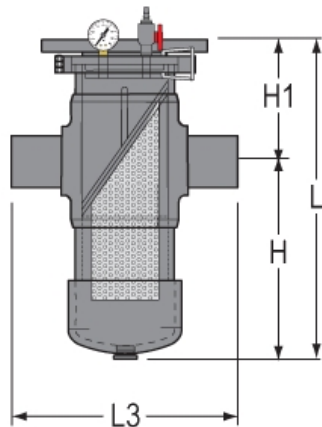

H = 13-13/16

H1 = 9

L = 22-13/16

L3 = 15

Cv = 172
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

