

Part No: BS37S6-120C

Filters & Strainers

Basket Strainers

Desc: 12 CPVC BASKET STRAINR SPG FKM S6 MESH

MSRP: 32284.31

Part Code: 297

Weight(lbs): 17.703

Weight(kg): 8.03

Weight(gm): 8030

Size: 12"


Color: GRAY

Material: CPVC

Connection Spigot

O-Ring FKM

Mesh Sieve # 6 = (1/8")

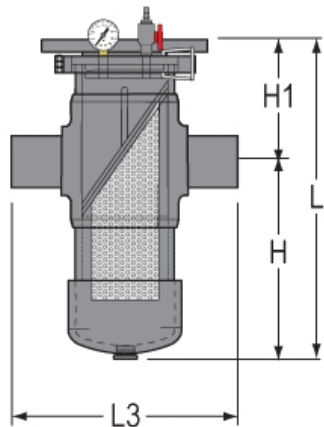

H = 34-5/16

H1 = 17-1/8

L = 51-1/2

L3 = 36- 1/4

Cv = 1063
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

