

Part No: CLIC-012CTS/010

**CLIC® TOP & CLIC® Pipe
Hangers & Spacers**

**CLIC® Top Premium Pipe
Hangers**

Desc: 1 IPS&1-1/4 CTS CLIC TOP GRAY PIPE CLAMP

MSRP: 7.66

Part Code: 893

Weight(lbs): 0.026

Weight(kg): 0.012

Weight(gm): 12

Size: 1 IPS & 1-1/4 CTS


Color: GRAY

Material: PolyAmide 12

Type IPS & CTS Pipe Hanger

Connection Pipe Clamp

Note Not Approved for FlameGuard®
Pipe

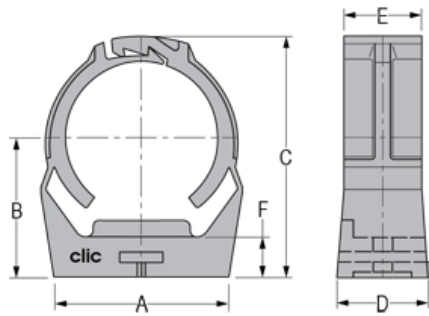

A = 1-1/2

B = 1-3/8

C = 2-5/32

D = 27/32

E = 11/16

F = 3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

