

Part No: CLIC-SP25

**CLIC® TOP & CLIC® Pipe
Hangers & Spacers**

CLIC® Top Stand-off Spacers

Desc: 1 CLIC TOP SPACER/25 MM

MSRP: 4.49

Part Code: 893

Weight(lbs): 0.013

Weight(kg): 0.006

Weight(gm): 6


Size: 1 / 25 MM

Color: GRAY

Material: PolyAmide 12

Type Stand-off Spacer

Note Fits all CLIC® Hangers

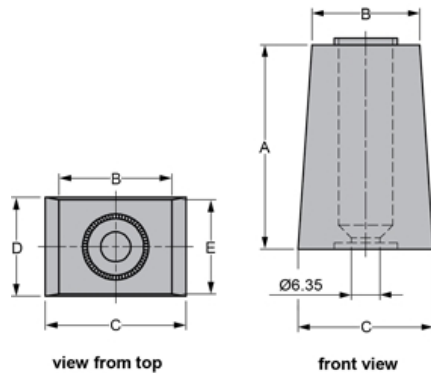

A = 1

B = 15/16

C = 1-3/16

D = 13/16

E = 25/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

