

Part No: D401-247G

Schedule 40 Gray

Tee

Desc: 2X1/2 PVC RED TEE DEEP SOC SCH40

MSRP: 13.77

Part Code: 043

Weight(lbs): 0.313

Weight(kg): 0.142

Weight(gm): 142


Size: 2"X2"X1/2"

Color:

Material: PVC

Connection Socket x Socket x Socket

Type Reduction

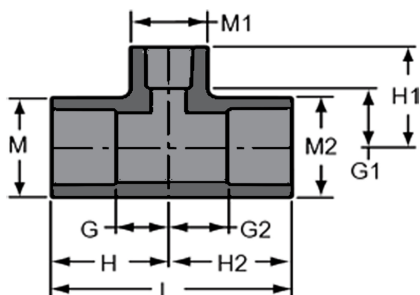

$$G = 9/16$$

$$G1 = 1-9/32$$

$$G2 = 9/16$$

$$H = 1-15/16$$

$$H1 = 2-17/32$$

$$H2 = 1-15/16$$

$$L = 3-7/8$$

$$M = 2-23/32$$

$$M1 = 1-3/32$$

$$M2 = 2-23/32$$

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

