

Part No: E1558-012

All

AV-1

Desc: 1 1/4 PVC TRUE UNION 2000 STANDARD BALL VALVE FLANGED FKM W/ 115VAC UNIDIRECTIONAL ACTUATOR, 25% DUTY CYCLE NEMA 4X ENCLOSURE W/ POSITION INDICATOR

MSRP: 563.86

Part Code: 500

Weight(lbs): 5.595

Weight(kg): 2.538

Weight(gm): 2538

Size:

Color:

Material:

Connection FKM Flanged


Under

Development

**Injection Molded Dimension References:**

- G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.
- H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.
- J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch
- L = Overall length of fittings; ± 1/16 inch.
- M = Outside diameter of socket/thread hub; ± 1/16 inch.
- N = Socket bottom to socket bottom; couplings; ± 1/16 inch.
- W = Height of cap; ± 1/16 inch

**Typical Molded Dimension References**

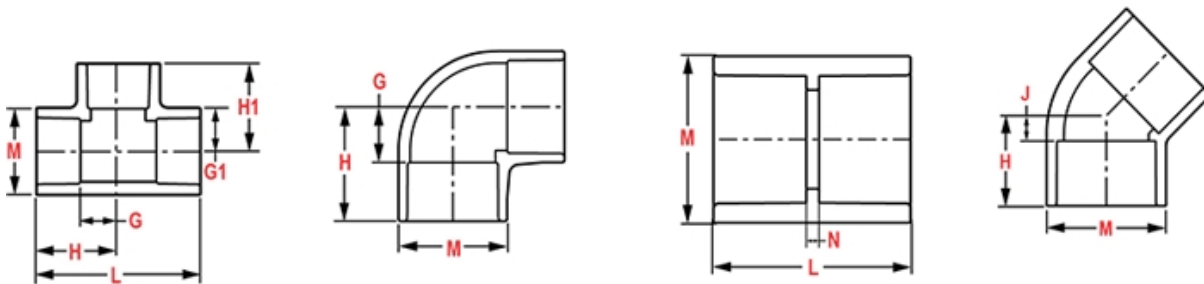

The information printed here is based on current information & product design at the time of publication and is subject to change without notification. Spears® ongoing commitment to product improvement may result in some variation. No representation, guarantees or warranties of any kind are as to its accuracy, suitability for particular application or results to be obtained therefrom. For verification of technical data or additional information, please contact Spears® Technical Service Department :: WEST COAST : (818) 364-1611 - EAST COAST : (717) 938-9006