

Part No: 1839V-005C

All

BV-1

Desc: 1/2 CPVC TU2KINDBV SOC/FPT FKM VENTD

MSRP: 144.09

Part Code: 602

Weight(lbs): 0.487

Weight(kg): 0.221


Weight(gm): 221

Size: 1/2

Color: GRAY

Material: CPVC

Connection Socket Ends FKM

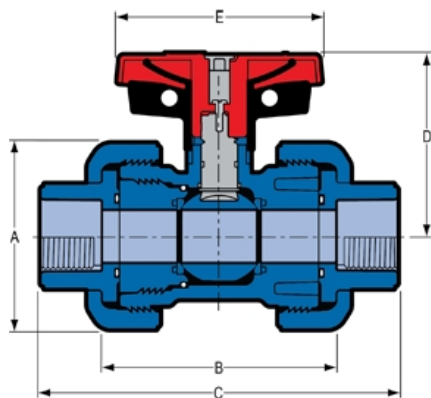

A = 1- 7/8

B = 2-31/32

C = 5- 7/32

D = 2- 9/16

E = 2-13/16

Cv = 29

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

