

Part No: EJ21-007CSR

Schedule 80 PVC & CPVC

Expansion Joint

Desc: 3/4 CPVC ELASTOMER EXP JOINT EPDM SR/FPT

MSRP: 349.69

Part Code: 085

Weight(lbs): 0.664

Weight(kg): 0.301

Weight(gm): 301

Size: 3/4"


Color: GRAY

Material: CPVC

Connection Elastomer SR Fipt

Bellow Type EPDM

Pressure Rating 150 psi @ 73° F

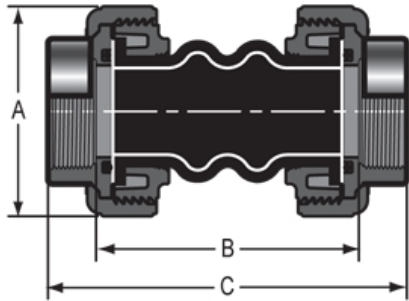

A = 2-11/32

B = 7

C = 8-1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

