

Part No: EJ21-015CSR

Schedule 80 PVC & CPVC

Expansion Joint

Desc: 1-1/2 CPVC ELASTOMER EXP JNT EPDM SR/FPT

MSRP: 566.43

Part Code: 085

Weight(lbs): 1.554

Weight(kg): 0.705

Weight(gm): 705

Size: 1-1/2"


Color: GRAY

Material: CPVC

Connection Elastomer SR Fipt

Bellow Type EPDM

Pressure Rating 150 psi @ 73° F

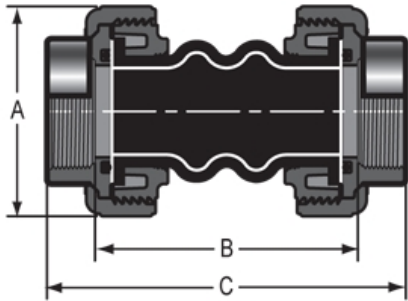

A = 3-19/32

B = 6-23/32

C = 8-19/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

