

Part No: EJ22-010C

Schedule 80 PVC & CPVC

Expansion Joint

Desc: 1 CPVC ELASTOMER EXP JOINT EPDM SOC

MSRP: 394.53

Part Code: 085

Weight(lbs): 0.851

Weight(kg): 0.386

Weight(gm): 386

Size: 1"


Color: GRAY

Material: CPVC

Connection Elastomer Socket

Bellow Type EPDM

Pressure Rating 150 psi @ 73° F

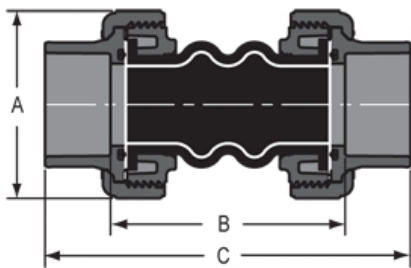

A = 2-21/32

B = 6-3/4

C = 9

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

