

Part No: FCKE-080C

Flanges & Cut-In Kit

Flange Cut-In Kit

Desc: 8 CPVC FLANGE CUT-IN KIT EPDM

MSRP: 4252.78

Part Code: 017

Weight(lbs): 37.245


Weight(kg): 16.894

Weight(gm): 16894

Size: 8

Color: GRAY

Material: CPVC

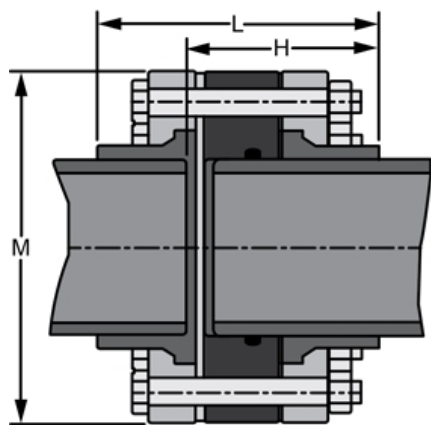

H = 6-7/8

L = 10-7/8

M = 13-9/16

Type Kit

Pressure Rating 150 psi @ 73° F

Gasket EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

