

Part No: FCKE-100C

Flanges & Cut-In Kit

Flange Cut-In Kit

Desc: 10 CPVC FLANGE CUT-IN KIT EPDM

MSRP: 6887.81

Part Code: 017

Weight(lbs): 59.113


Weight(kg): 26.813

Weight(gm): 26813

Size: 10

Color: GRAY

Material: CPVC

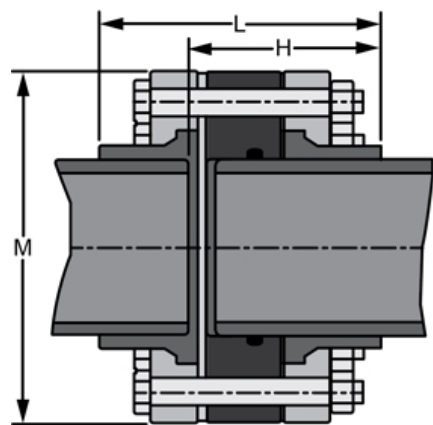

H = 8-1/2

L = 13-1/2

M = 16

Type Kit

Pressure Rating 150 psi @ 73° F

Gasket EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

