

Part No: FCKV-060C

Flanges & Cut-In Kit

Flange Cut-In Kit

Desc: 6 CPVC FLANGE CUT-IN KIT FKM

MSRP: 3817.53

Part Code: 017

Weight(lbs): 25.43


Weight(kg): 11.535

Weight(gm): 11535

Size: 6

Color: GRAY

Material: CPVC

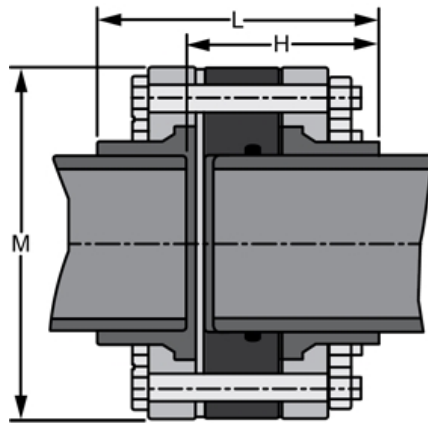

H = 6

L = 9

M = 11-1/4

Type Kit

Pressure Rating 150 psi @ 73° F

Gasket FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

