

Part No: FTP-005GS

FlameGuard®

Test Plug

Desc: 1/2 PVC TEST PLUG FOR GASKETED ADAPTER

MSRP: 2.69

Part Code: 004

Weight(lbs): 0.055


Weight(kg): 0.025

Weight(gm): 25

Size: 1/2

Color: GRAY

Material: PVC

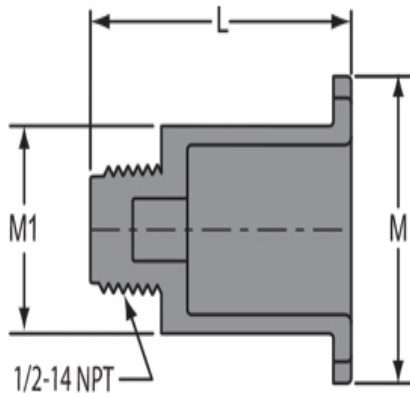

L = 1-25/32

M = 2- 1/32

M1 = 1- 1/4

Type Gasket Sealed

Connection Mipt

Note For Pressure Testing Only

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

