

Part No: G0002-005P

Lab Specialty

Gauge Guards

Desc: 1/2 GFPP GAUGE GUARD LESS GAUGE EPDM

MSRP: 196.01

Part Code: 626

Weight(lbs): 0.243


Weight(kg): 0.11

Weight(gm): 110

Size: 1/2

Color: NATURAL

Material: Polypropylene

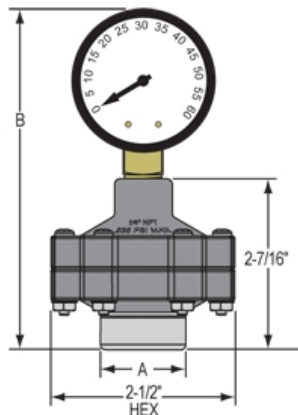

A = 1-3/16

Type Gauge Guard
Connection SR Fipt
O-Ring EPDM
Pressure Rating 235 psi @ 73° F
Diaphragm EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

