

Part No: G0004-002C

Lab Specialty

Gauge Guards

Desc: 1/4 CPVC GAUGE GUARD LESS GAUGE PTFE

MSRP: 226.69

Part Code: 625

Weight(lbs): 0.373


Weight(kg): 0.169

Weight(gm): 169

Size: 1/4

Color: GRAY

Material: CPVC

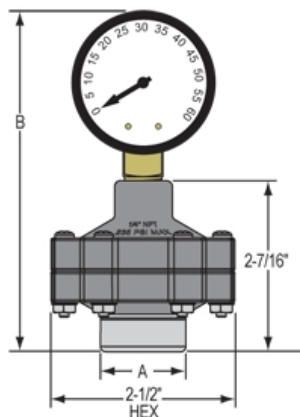

A = 7/8

Type Gauge Guard
Connection SR Fipt
O-Ring EPDM
Pressure Rating 235 psi @ 73° F
Diaphragm PTFE

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

