

**Part No:** G0004-005C

**Lab Specialty**

**Gauge Guards**

**Desc:** 1/2 CPVC GAUGE GUARD LESS GAUGE PTFE

**MSRP:** 226.69

**Part Code:** 625

**Weight(lbs):** 0.362


**Weight(kg):** 0.164

**Weight(gm):** 164

**Size:** 1/2

**Color:** GRAY

**Material:** CPVC

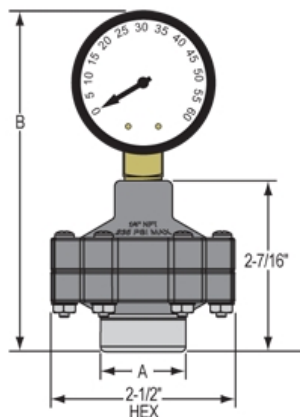

**A =** 1-3/16

**Type** Gauge Guard  
**Connection** SR Fipt  
**O-Ring** EPDM  
**Pressure Rating** 235 psi @ 73° F  
**Diaphragm** PTFE

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

