

**Part No:** G0154-002P

**Lab Specialty**

**Gauge Guards**

**Desc:** 1/4 GFPP 0-15 PSI GAUGE GUARD PTFE

**MSRP:** 298.18

**Part Code:** 626

**Weight(lbs):** 0.538


**Weight(kg):** 0.244

**Weight(gm):** 244

**Size:** 1/4

**Color:** NATURAL

**Material:** Polypropylene

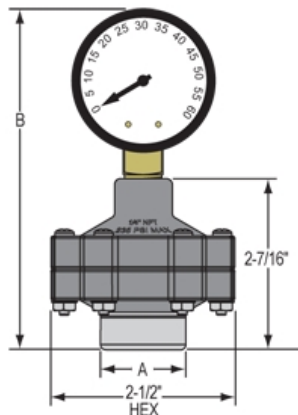

**A** = 7/8

**B** = 5

**Type** Gauge Guard  
**Connection** SR Fipt  
**O-Ring** EPDM  
**Pressure Rating** 235 psi @ 73° F  
**Diaphragm** PTFE

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

