

Part No: G0602-005C

Lab Specialty

Gauge Guards

Desc: 1/2 CPVC 0-60 PSI GAUGE GUARD EPDM

MSRP: 347.49

Part Code: 625

Weight(lbs): 0.615


Weight(kg): 0.279

Weight(gm): 279

Size: 1/2

Color: GRAY

Material: CPVC

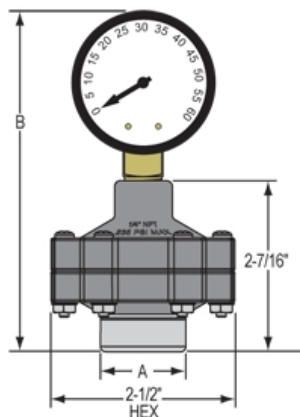

A = 1-3/16

B = 5

Type Gauge Guard
Connection SR Fipt
O-Ring EPDM
Pressure Rating 235 psi @ 73° F
Diaphragm EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

