

Part No: G0604-002C

Lab Specialty

Gauge Guards

Desc: 1/4 CPVC 0-60 PSI GAUGE GUARD PTFE

MSRP: 361.8

Part Code: 625

Weight(lbs): 0.646


Weight(kg): 0.293

Weight(gm): 293

Size: 1/4

Color: GRAY

Material: CPVC

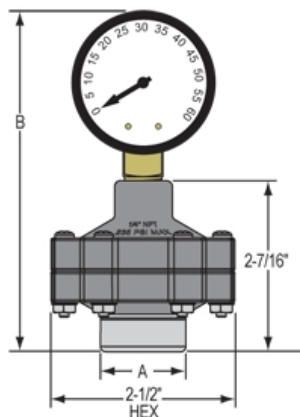

A = 7/8

B = 5

Type Gauge Guard
Connection SR Fipt
O-Ring EPDM
Pressure Rating 235 psi @ 73° F
Diaphragm PTFE

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

