

Part No: G1004-002BL

Low Extractable

Gauge Guard

Desc: 1/4 LE 0-100 PSI GAUGE GUARD PTFE

MSRP: 348.26

Part Code: 623

Weight(lbs): 0.591


Weight(kg): 0.268

Weight(gm): 268

Size: 1/4

Color: BLUE

Material: PVC LE

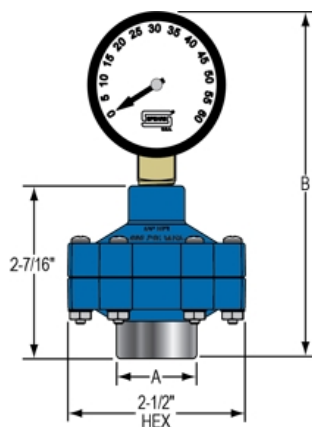

A = 7/8

B = 5

Type Gauge Guard

Connection SR Fipt

O-Ring EPDM

Pressure Rating 235 psi @ 73° F

Diaphragm PTFE

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

