

Part No: G1602-002P

Lab Specialty

Gauge Guards

Desc: 1/4 GFPP 0-160 PSI GAUGE GUARD EPDM

MSRP: 286.37

Part Code: 626

Weight(lbs): 0.525


Weight(kg): 0.238

Weight(gm): 238

Size: 1/4

Color: NATURAL

Material: Polypropylene

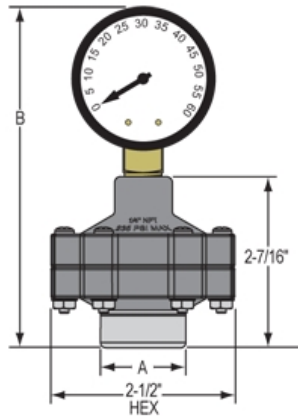

A = 7/8

B = 5

Type Gauge Guard
Connection SR Fipt
O-Ring EPDM
Pressure Rating 235 psi @ 73° F
Diaphragm EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

