

Part No: G2003-002

Lab Specialty

Gauge Guards

Desc: 1/4 PVC 0-200 PSI GAUGE GUARD FKM

MSRP: 278.27

Part Code: 624

Weight(lbs): 0.606


Weight(kg): 0.275

Weight(gm): 275

Size: 1/4

Color: GRAY

Material: PVC

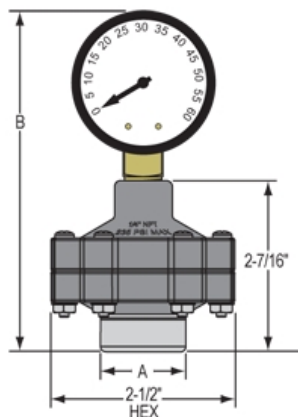

A = 7/8

B = 5

Type Gauge Guard

Connection SR Fipt

O-Ring EPDM

Pressure Rating 235 psi @ 73° F

Diaphragm FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

