

Part No: G3004-005P

Lab Specialty

Gauge Guards

Desc: 1/2 GFPP 0-300 PSI GAUGE GUARD PTFE

MSRP: 298.18

Part Code: 626

Weight(lbs): 0.545


Weight(kg): 0.247

Weight(gm): 247

Size: 1/2

Color: NATURAL

Material: Polypropylene

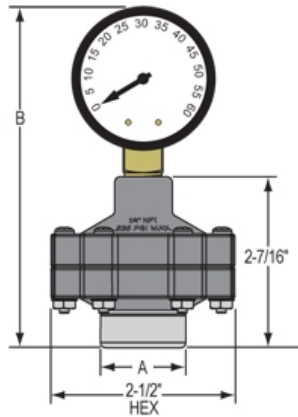

A = 1-3/16

B = 5

Type Gauge Guard
Connection SR Fipt
O-Ring EPDM
Pressure Rating 235 psi @ 73° F
Diaphragm PTFE

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

