

Part No: GL4129-005

EverTUFF® CTS

GripLoc™ Couplings

Desc: 1/2 CTS CPVC GRIPLOC COUPLING

MSRP: 23.92

Part Code: 135

Weight(lbs): 0.086

Weight(kg): 0.039

Weight(gm): 39

Size: 1/2

Color: TAN

Material: CPVC

Connection GripLoc™ Socket

Type GripLoc™


Note Use NO Solvent Cement

WARNING DO NOT INSERT FINGERS

NSF® Certified LEAD FREE

O-Ring EPDM

Pressure Rating 100 psi Max Internal Pressure @ 180° F

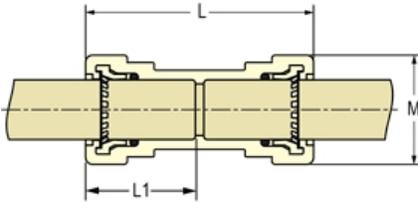

L1 = 1-5/16

L = 2-3/4

M = 1-1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch


L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

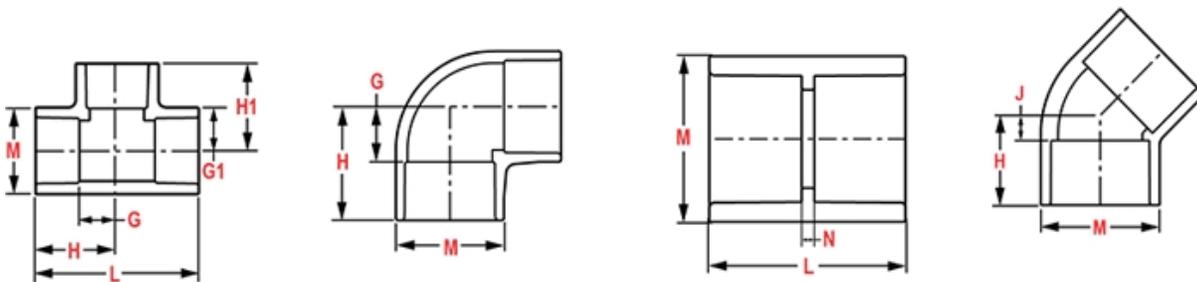

The information printed here is based on current information & product design at the time of publication and is subject to change without notification. Spears® ongoing commitment to product improvement may result in some variation. No representation, guarantees or warranties of any kind are as to its accuracy, suitability for particular application or results to be obtained therefrom. For verification of technical data or additional information, please contact Spears® Technical Service Department :: WEST COAST : (818) 364-1611 - EAST COAST : (717) 938-9006