

Part No: GL4129-010

EverTUFF® CTS

GripLoc™ Couplings

Desc: 1 CTS CPVC GRIPLOC COUPLING

MSRP: 31.57

Part Code: 135

Weight(lbs): 0.269

Weight(kg): 0.122

Weight(gm): 122

Size: 1

Color: TAN

Material: CPVC

Connection GripLoc™ Socket

Type GripLoc™


Note Use NO Solvent Cement

WARNING DO NOT INSERT FINGERS

NSF® Certified LEAD FREE

O-Ring EPDM

Pressure Rating 100 psi Max Internal Pressure @ 180° F

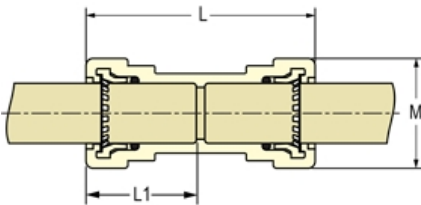

L = 4

M = 2

L1 = 1-29/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

