

Part No: GL4206-010

FlameGuard®

GripLoc™ Elbow

Desc: 1 CPVC FLAMEGUARD GRIPLOC 90 ELBOW

MSRP: 33.4

Part Code: 134

Weight(lbs): 0.54


Weight(kg): 0.245

Weight(gm): 245

Size: 1

Color: ORANGE

Material: CPVC

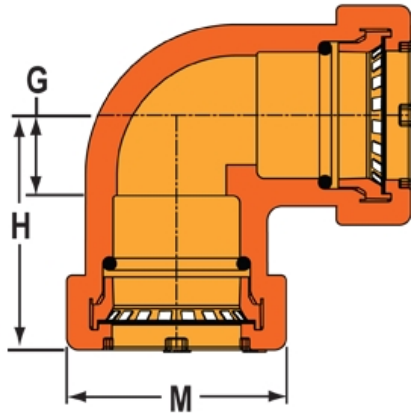

G = 27/32

H = 2-1/2

M = 2-5/16

Type GripLoc™
Connection GripLoc™ Socket

O-Ring EPDM

WARNING DO NOT INSERT FINGERS

Pressure Rating 175 psi (1.21 Mpa) @ 150° F

NSF® Certified LEAD FREE

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

