

Part No: GL4247-007

FlameGuard®

GripLoc™ Cap

Desc: 3/4 CPVC FLAMEGUARD GRIPLOC CAP

MSRP: 25.97

Part Code: 134

Weight(lbs): 0.143


Weight(kg): 0.065

Weight(gm): 65

Size: 3/4

Color: ORANGE

Material: CPVC

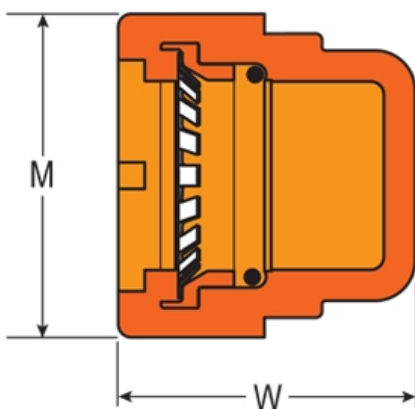

M = 1-15/16

W = 1-11/16

Type GripLoc™

Connection GripLoc™ Socket

O-Ring EPDM

WARNING DO NOT INSERT FINGERS

Pressure Rating 175 psi (1.21 Mpa) @ 150° F

NSF® Certified LEAD FREE

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

