

**Part No:** GL447-015C

**Schedule 80 PVC & CPVC**

**GripLoc™ Cap**

**Desc:** 1-1/2 CPVC GRIPLOC CAP

**MSRP:** 50.19

**Part Code:** 132

**Weight(lbs):** 0.351


**Weight(kg):** 0.159

**Weight(gm):** 159

**Size:** 1-1/2

**Color:** GRAY

**Material:** CPVC

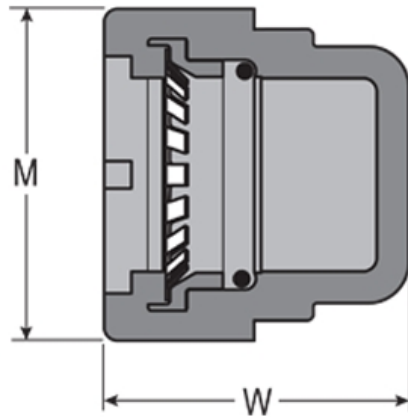

**M** = 3

**W** = 2-5/16

**Type** GripLoc™

**Connection** GripLoc™ Socket

**O-Ring** EPDM

**WARNING** DO NOT INSERT FINGERS

**Pressure Rating** 235 psi @ 73°F

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

